
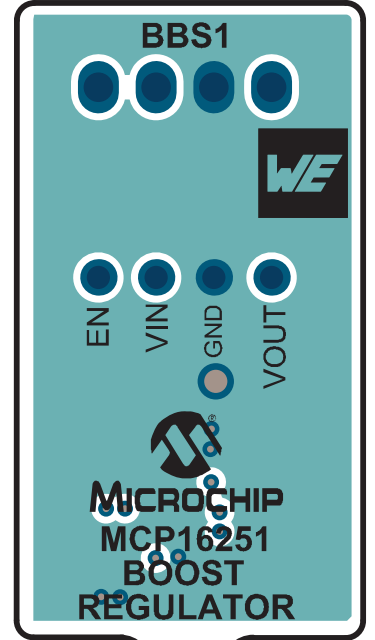
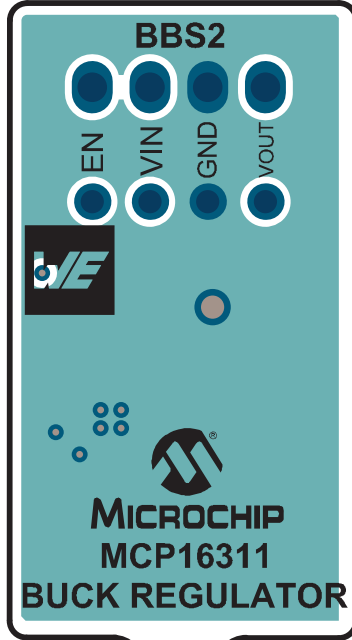
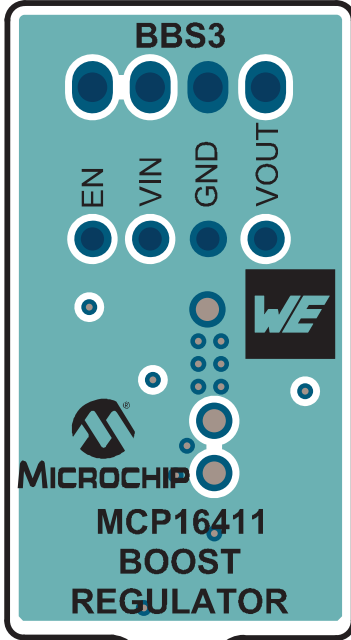


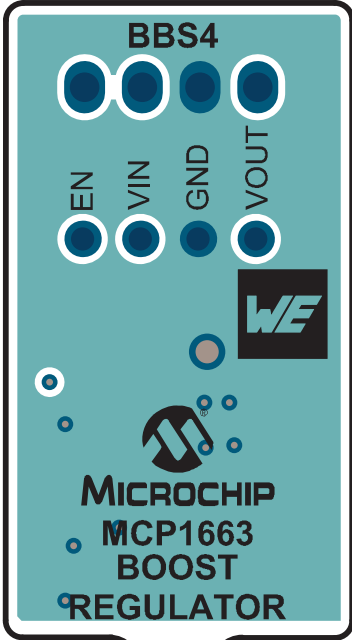

Vin: 2.4-5.5V
Vo: 12V
Io: 200mA

CE

Vin: 1.5V
Vo: 3.3V
Io: 200mA

50

Vin: 4.5V-30V
Vo: 3.3V
Io: 1A

Vin: 1.5V
Vo: 3.3V
Io: 100mA

Vin: 2.4-5.5V
Vo: 24V
Io: 150mA

UK CA **RoHS**

04-12242-R1

