


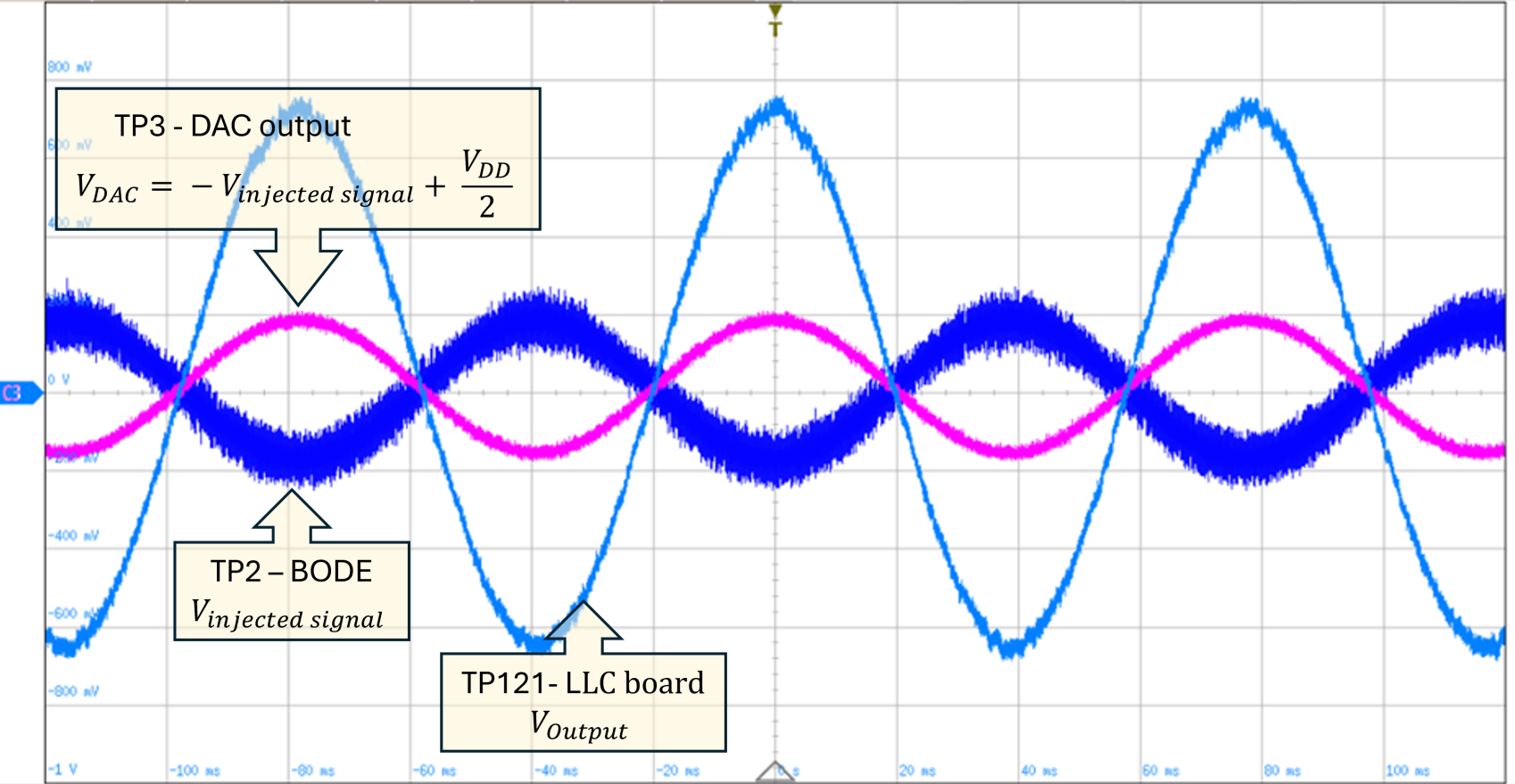

C1 Vpp: 388 mV C2 Vpp: 1.454 V C3 f: 12.7942 Hz

C1 200 mV/ AC 10:1 C2 200 mV/ BW AC 10:1 C3 200 mV/ BW AC 10:1 C4 500 mV/ BW DC 10:1

