



PRODUCT NUMBER: 836-22-003-10-001101

836-22-0XX-10-001101

Mid profile, Through-hole mount

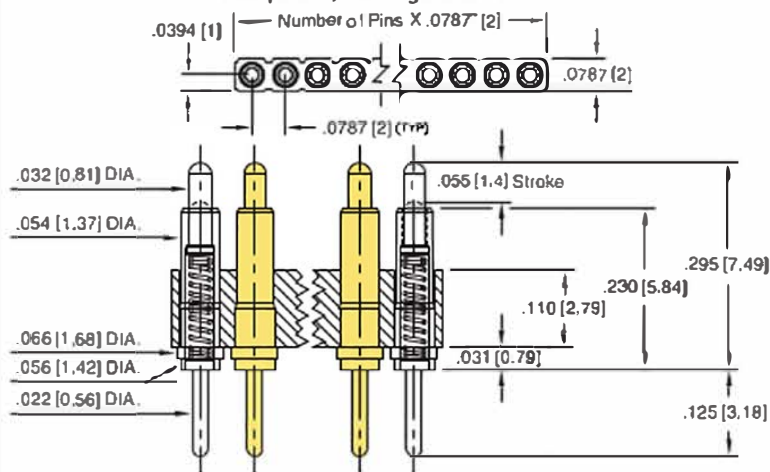

Suggested P.C.B. Footprint

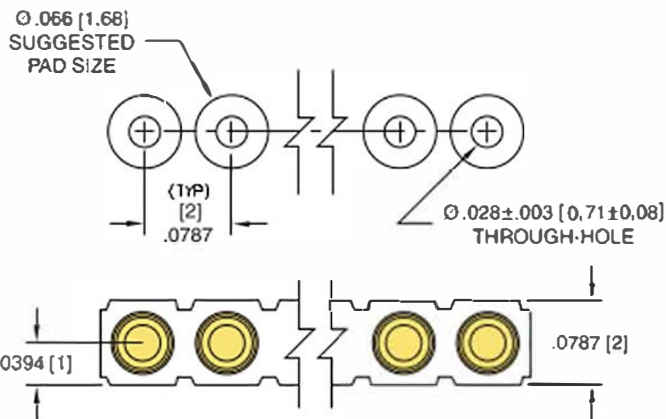

DESCRIPTION

Spring-Loaded Pogo Pin Header Strip

PCB Mount Spring-Loaded Header Vertical

Mount Through-Hole

Rows: Single Row (1)

Pitch: .079" (2.007 mm)

Stroke: .055" (1.397 mm)

Clip Grid: 10

Pin Window Pattern 001

Plating Code: 22

Shell: 20 μ Gold over 100 μ Nickel

Inner Contact: (Spring) 10 μ Gold

Insulator Pin Clip Type: 101

Initial Height: .295" (7.493 mm) Mounting

Type: Through Hole Solder Mount Insulator

Information:

Nylon 46 High Temperature