


EN55022 Class B - CISPR 9 kHz (1 kHz Steps)

- Fixed Frequency Voltage Mode, VIN = 9V, VOUT = 3.3V, Iout = 3.3 A -

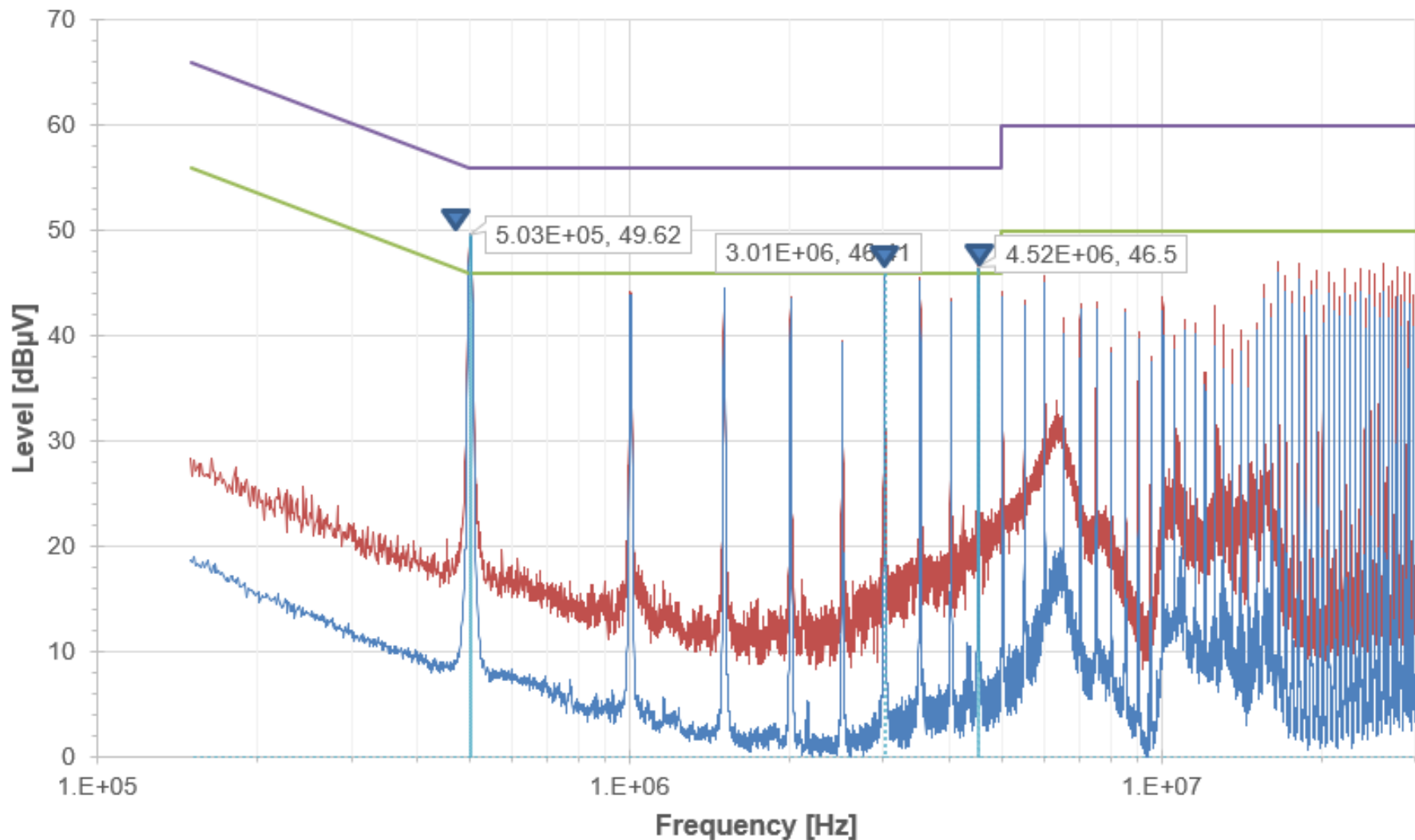

— PEAK LEVEL [dBµV] — AVG LEVEL [dBµV] — EN55022_Class B AVG
— EN55022_Class B QPEAK AVG MAX