


100Ω ±10% differential trace impedance
Routing top or bottom

MIPI-CSI

Matched Net Lengths [Tolerance = 0.25mm]

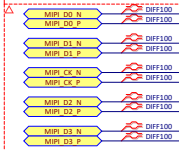

MIPI_CSI_GPIO0_PB12
MIPI_CSI_GPIO1_PB26

MIPI_CSI_GPIO1_PB26

DISP_I2C_CLK_PB5
DISP_I2C_DATA_PB4

FLEXCOMB_ID0_TWICK

FLEXCOMB_ID0_TWIO

VDD_3V3

VDD_MIPI

R90
10k
0402
1%
DNP

VDD_3V3
5V_MAIN

J12

HDR-1.27 Male 1x3

JP6

501951-2230

J12 pin #1-2 to select 3.3V

J12 pin #2-3 to select 5V

MIPI_CSI_GPIO1_PB26