
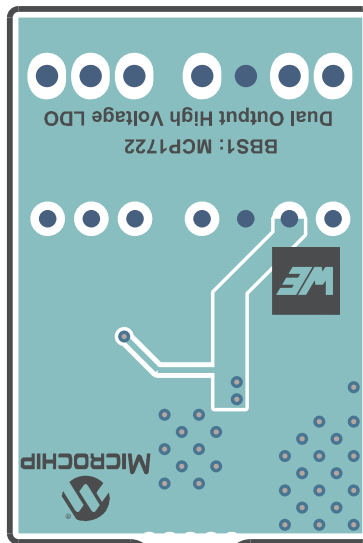


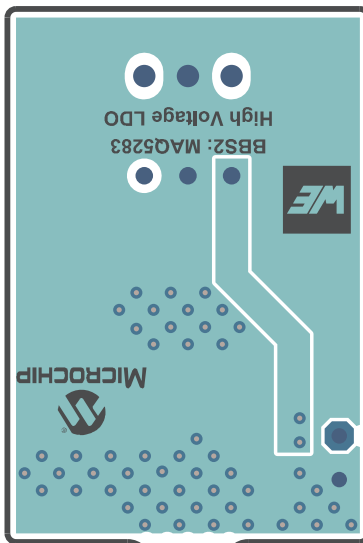

Vin: 2.1 - 5V
Out: 1.8V & 500mA

Vin: 3.5 - 5.5V
Out: 3.3V & 300mA

Vin: 3.8 - 4.5V
Out: 3.3V & 1A

Vin: 3.5 - 12V
Out: 1.8V & 50mA

Vin: 6.2 - 24V
Out: 5V & 100mA

Vin: 5.5 - 6V
Out: 5V & 1A

Vin: 6 - 48V
Out: 5V & 80mA

Vin: 6 - 100V
Out: 3V & 20mA

Vin: 13 - 24V
Out1: 10V & 50mA
Out2: 3.3V & 50mA

CE

50

UK CA

RoHS

04-12727-RI

