


SWITCHER OUTPUT
(2V/div)

OUTPUT VOLTAGE
(1mV/div)

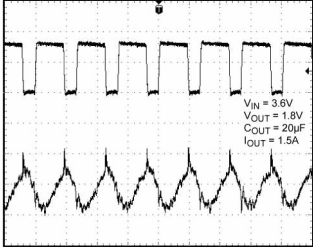

$V_{IN} = 3.6V$
 $V_{OUT} = 1.8V$
 $C_{OUT} = 20\mu F$
 $I_{OUT} = 1.5A$

Time (400ns/div)